


# Service Disconnects for Vektor Laboratory Exhaust

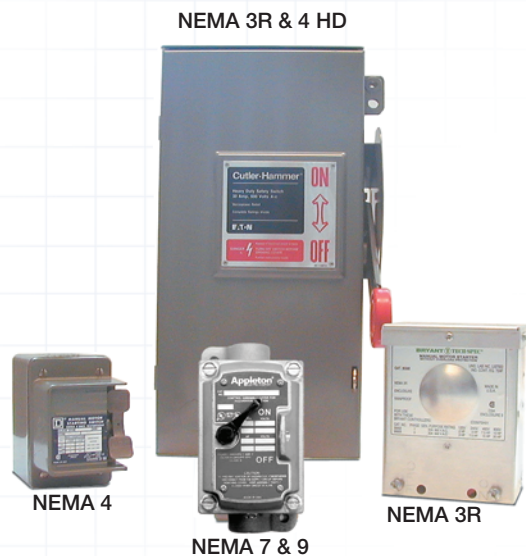

Greenheck's Vektor laboratory exhaust systems are available with factory mounted and wired service disconnect switches. These switches are available to disconnect power prior to inspection or performing field service work.



### Safety Disconnect Switch Features

- Available in NEMA-7 & 9, NEMA-3R (rain resistant), or NEMA-4 (watertight and dust tight) enclosures
- Available for 50 or 60 Hz power:  
50 Hz: 190, 220, 380, 440 volt  
60 Hz: 208, 230, 460, 575 volt
- Visible switch blades for positive "OFF" indication (some models)
- Padlock provision for the OFF position
- Horsepower rated for motor applications
- UL listed electrical components

Note: NEMA-7 & 9 are offered, but not factory mounted

Vektor Service Disconnect Features and Options	Vektor™-H	Vektor™-MD Vektor™-CD
Toggle Type Switch	Yes	No
Heavy Duty Switch	Optional	Yes
Fusible Disconnect	Optional	Optional
Two-Speed Disconnect Switches	Optional	Optional
Disconnect Switches Wired for Y-Delta	Optional	Optional

### Advantages:

- All factory supplied single speed NEMA-3R and NEMA-4 disconnects ship factory mounted and wired for motors up to 125 hp
- All wiring is enclosed in non-metallic, liquid-tight conduit
- All electrical connections are factory tested before shipment

As a result of our commitment to continuous improvement, Greenheck reserves the right to change specifications without notice.



Prepared to Support  
Green Building Efforts

