






# GREENHECK

## Volume Controller

### For CRD-1, -1LP, -1WJ, -1WT & 2

Greenheck's volume controller option allows adjustment of damper blades to balance airflow. This option is factory mounted and is available with 165°F or 212°F (74°C or 100°C) fusible links. The fusible link is easily replaceable in the field. The volume controller extends 1 in. (25mm) below the frame on CRD-1 and CRD-1LP models and ¾ in. (19mm) on CRD-2 when standard frame is selected. If the volume controller can not extend past the frame, select a bottom frame extension.

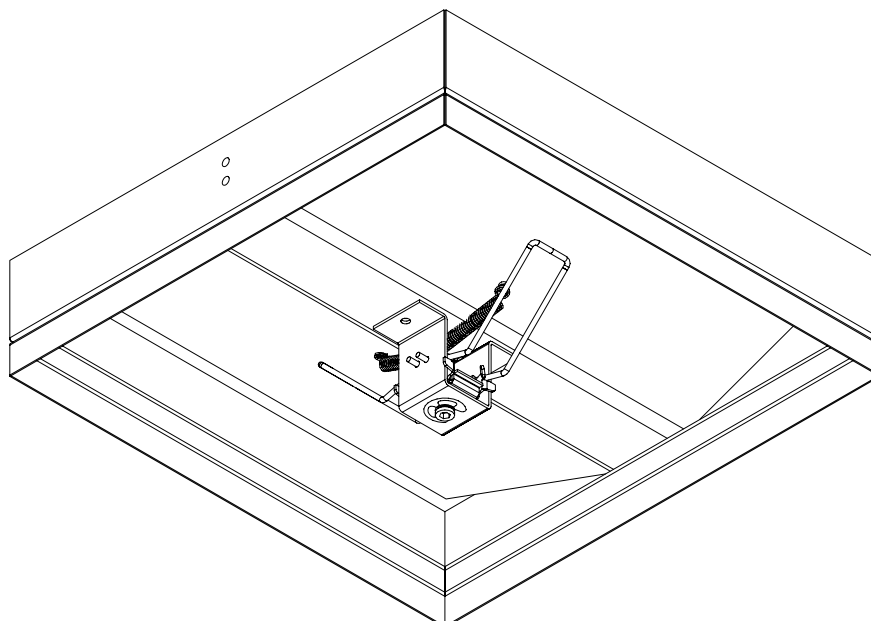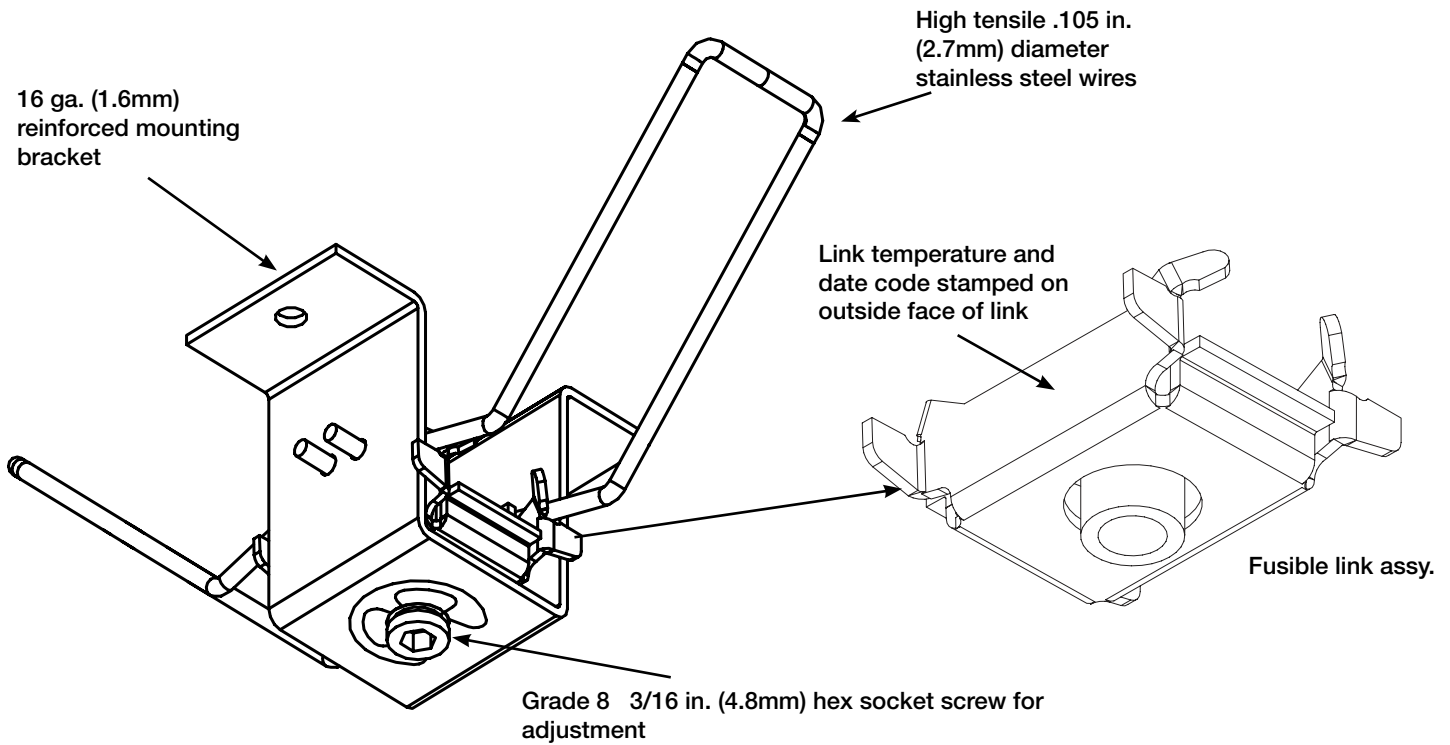

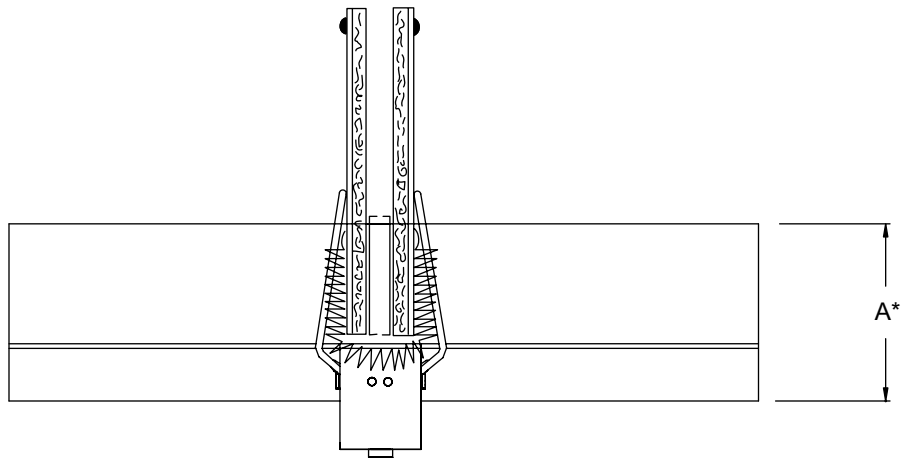

\* This dimension is for standard frame only. CRD-1 standard frame is 2 11/16 in. (68mm). CRD-2 standard frame is 3 7/16 in. (87mm). The volume controller extends 1 in. (25mm) below the frame.

