

Greenheck drive slip connections (S & Drive) are used on the side of the hemmed sleeves and the S-slip joints are used on the top and bottom. Standard drive slips are UL tested breakaway connections on dampers 20 in. (508mm) high and less.

**“UL CLASSIFIED
(see complete marking on product)”**
**“UL CLASSIFIED to Canadian safety standards
(see complete marking on product)”**
 Standards UL 555 & 555S
 Classifications Filed at UL under Listing #R13317


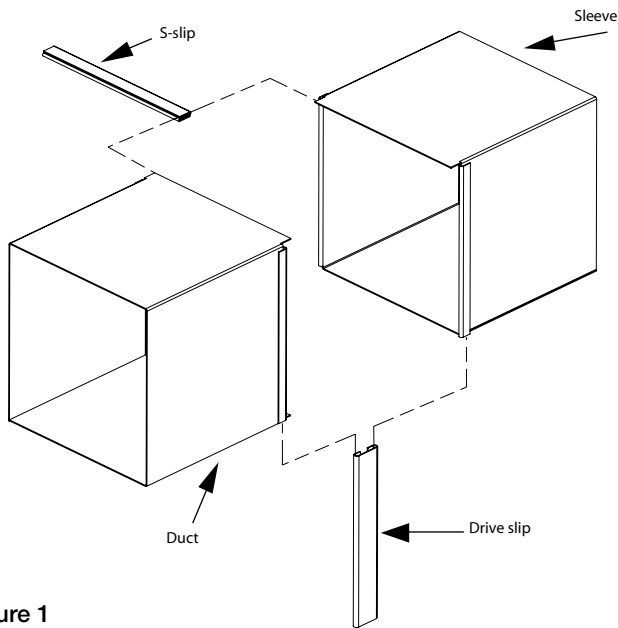



Figure 1

Note: Drive Slip connections are not recommended for duct pressures above 1 in. wg (249 Pa).

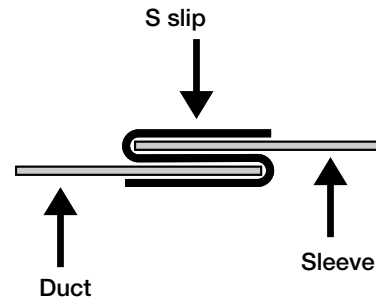

Top and Bottom
Duct to sleeve
Connection

Figure 2

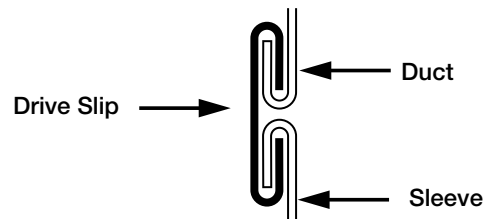

Vertical Sides Duct
to sleeve connection

Figure 3