



SKU  
SP-AP0511W


Job Name:  
Mark:  
Submitted By:  
Date: 05/27/2026

## Bathroom Exhaust Fan, Product # SP-AP0511W, 30-110 CFM



Model SP-AP features a virtually silent electronically commutated (EC) motor with three built-in, high-speed airflow settings (50, 80 or 110 cfm) and a handful of plug and play sensors available as add-ons.

- ENERGY STAR rated
- Virtually silent EC motor with 3 high speeds (50-80-110 CFM)
- Constant CFM technology
- Plug and play sensors available
- Universal 4", 5" or 6" duct connector
- Easy installation bracket
- Two speed capable with integral time delay

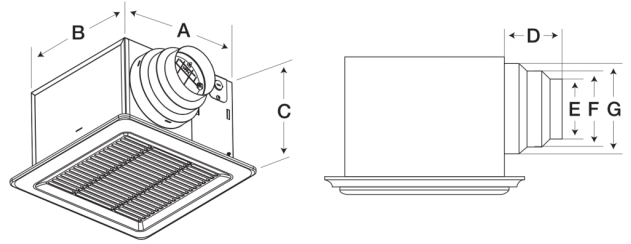


A	B	C	D	E	F	G
10.25 in	10.375 in	7.375 in	3.75 in	3.875 in	4.875 in	5.875 in

### Certifications

ETL  
Home Ventilating Institute (HVI)

### Performance Characteristics

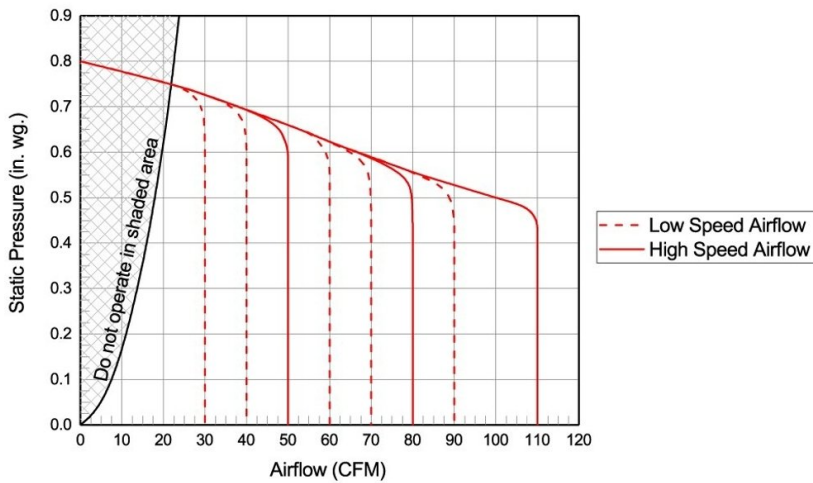

### Construction Features

Drive Type	Direct Drive
Includes	Backdraft damper Mounting brackets
Certifications	ETL Home Ventilating Institute (HVI)
Speed Controllable	Yes

### Motor Information

Voltage	115
Motor Included	Yes

### Air and Sound Performance

Watts	Max Fan RPM	Min Fan RPM	Ps (in. wg)	0	0.1	0.125	0.25	0.375	0.5	0.625
				CFM	Sones	CFM	Sones	CFM	Sones	CFM
16.5	820	820	CFM	50	50	50	50	50	50	50
			Sones	<0.3	<0.3	<0.3	0.6	1.5	2.5	3
18.1	831	831	CFM	80	80	80	80	80	80	60
			Sones	<0.3	<0.3	<0.3	0.8	1.4	2	3
20.1	861	861	CFM	110	110	110	110	110	105	58
			Sones	0.4	0.4	0.5	0.8	1.3	2	3

## California Residents

 **WARNING**

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)