



SKU
SP-A390-VG-QD

Job Name:
Mark:
Submitted By:
Date: 04/04/2026

Bathroom Exhaust Fan, Model SP-A390-VG, 115/208-230/277V, 1Ph, 93-410 CFM




Model SP-A direct drive, ceiling mounted fan is designed to provide the lowest sounds levels for bathroom exhaust. Units feature an insulated housing and are ideal for residential, multi-family or hotel applications. Model CSP-A390-VG features a tri-voltage design to operate at 115/208-230/277V. Vari-Green EC motor technology included for maximum fan controllability.

- ENERGY STAR rated
- Acoustic insulation absorbs sound ensuring quiet operation
- Spring loaded aluminum backdraft damper eliminates rattling
- External electrical access reduces installation time
- Speed controllable
- Designer grille included


Certifications

AMCA Air & Sound
UL/cUL 507

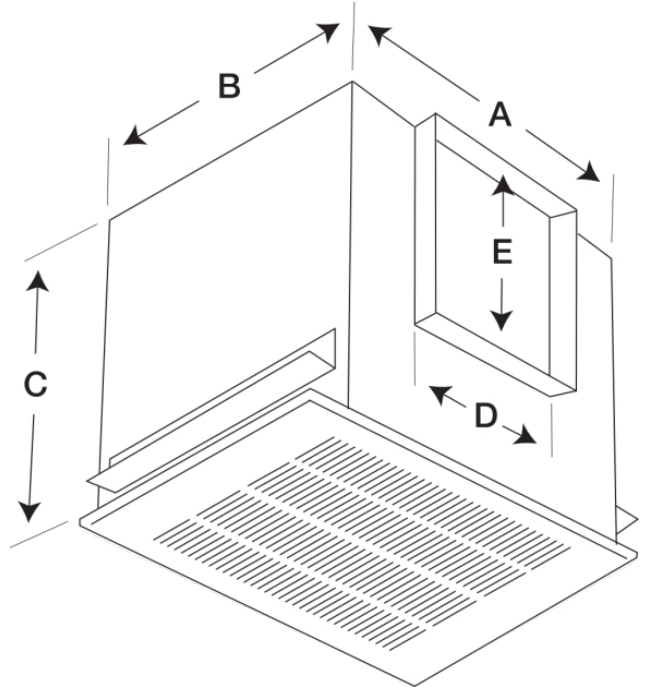

A	B	C	D	E
14 in	11.875 in	11.25 in	8 in	8 in

Performance Characteristics

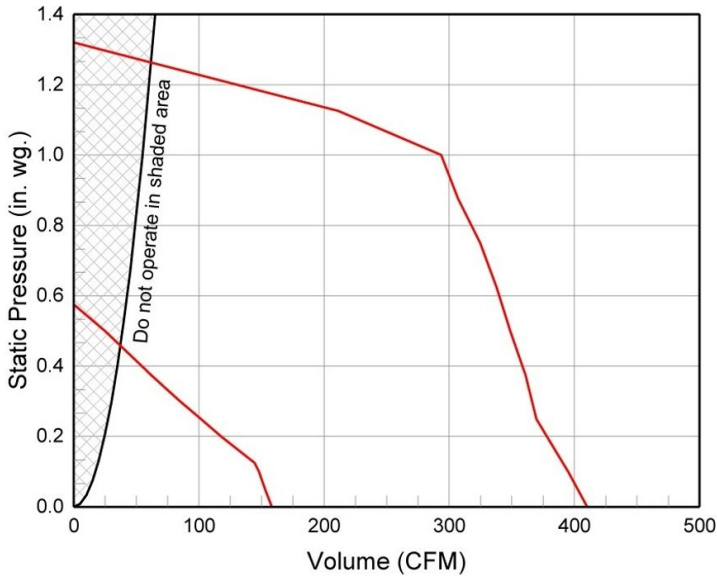

Construction Features

Housing Material	Galvanized Steel
Drive Type	Direct Drive
Impeller Type	Centrifugal Wheel
Impeller Material	Polypropylene
Includes	Backdraft damper Mounting brackets
Certifications	AMCA Air & Sound UL/cUL 507
Speed Controllable	Yes

Motor Information

Motor Phase	1
Voltage	115/208-230 277
Motor Enclosure	Totally Enclosed Non-Vented
RPM	1750
Motor Included	Yes

Air and Sound Performance

Watts	Max Fan RPM	Min Fan RPM	Ps (in. wg.)	0	0.1	0.125	0.25	0.375	0.5	0.625	0.75	0.875	1
47	935	935	CFM	276	251	248	233	215	196	173	146	120	93
			Sones	2	2	2	2.5	3	3.5	4	5	6	6
100	1340	1340	CFM	410	395	390	370	361	349	338	325	307	294
			Sones	5	5	5	5	5	6	6.5	7	7	7

California Residents

 **WARNING**

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit www.P65Warnings.ca.gov