




SKU
328130

Job Name:
Mark:
Submitted By:
Date: 04/05/2026

Vari-Green Motor, FA716B4610, 0.25HP, 1800RPM, 110/220-240//115/208-230 & 277V, 50/60HZ, 1PH, Product # 328130

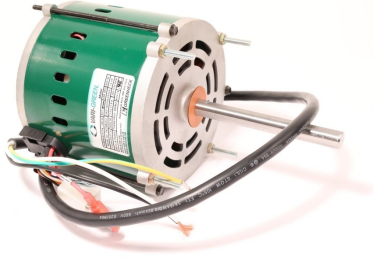

Performance Characteristics

Power	Speed	Voltage	Frequency	Phase	Full Load Amp Draw
0.25 HP	1800	220	50	1	2.1
0.25 HP	1800	277	60	1	1.8
0.25 HP	1800	230	50	1	2.1
0.25 HP	1800	208	60	1	2.1
0.25 HP	1800	230	60	1	2.1
0.25 HP	1800	277	50	1	1.8
0.25 HP	1800	208	50	1	2.1
0.25 HP	1800	110	50	1	3.5
0.25 HP	1800	240	60	1	2.1
0.25 HP	1800	115	60	1	3.5
0.25 HP	1800	115	50	1	3.5
0.25 HP	1800	240	50	1	2.1

Specifications

Base Type	Extended Thru-Bolt Mount	Country of Origin (Primary)	US
Explosion Proof	n/a	Frame Size	n/a
Frame Type	n/a	Housing Material	Rolled Steel
Motor Enclosure	n/a	Motor Insulation	B
Motor Phase	1	Motor Type	BrushlessDC
Return Eligibility	Non-returnable, customized, or special-order item	Shipping Type	Freight
Thermal Protection	AutoOverload		

Dimensions

Height	5 1/2 in	Length	10 in
Weight	8 lbs	Width	5 1/2 in

California Residents

⚠ WARNING

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit www.P65Warnings.ca.gov