




SKU  
356567

Job Name:  
Mark:  
Submitted By:  
Date: 06/08/2025

## Motor, 35E5455L158G1, 0.75HP, 1800 RPM, 208-230/460V, 60Hz, 3Ph, Product # 356567

### Performance Characteristics

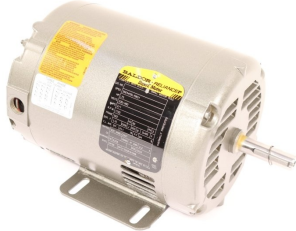

Power	Speed	Voltage	Frequency	Phase	Full Load Amp Draw
0.75 HP	1800	460	60	3	1
0.75 HP	1800	208	60	3	2.2
0.75 HP	1800	230	60	3	2

### Specifications

Base Type	Rigid Base	Country of Origin (Primary)	US
Explosion Proof	No	Frame Size	56
Frame Type	n/a	Housing Material	Rolled Steel
Motor Enclosure	Open Drip Proof	Motor Insulation	F
Motor Phase	3	Motor Type	NEMA
Shipping Type	Parcel	Thermal Protection	AutoOverload

### Dimensions

Shaft Diameter	0.625 in	Weight	35 lbs
----------------	----------	--------	--------