




SKU  
319356

Job Name:  
Mark:  
Submitted By:  
Date: 04/05/2026

## Vari-Green Motor - 1/10 HP, 115V, 208-230V, 277V, 1725RPM , Product # 319356

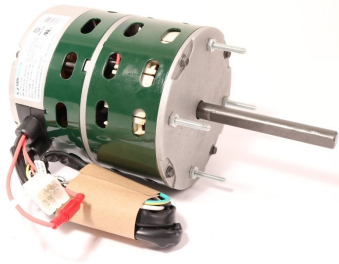

### Performance Characteristics

Power	Speed	Voltage	Frequency	Phase	Full Load Amp Draw
0.1 HP	1800	115	60	1	1.38
0.1 HP	1800	208	60	1	0.84
0.1 HP	1800	208	50	1	0.84
0.1 HP	1800	277	60	1	0.73
0.1 HP	1800	230	60	1	0.84
0.1 HP	1800	277	50	1	0.73
0.1 HP	1800	240	50	1	0.84
0.1 HP	1800	220	50	1	0.84
0.1 HP	1800	110	50	1	1.38
0.1 HP	1800	230	50	1	0.84
0.1 HP	1800	115	50	1	1.38

### Specifications

<b>Base Type</b>	Extended Thru-Bolt Mount	<b>Country of Origin (Primary)</b>	CN,VN
<b>Explosion Proof</b>	n/a	<b>Frame Size</b>	n/a
<b>Frame Type</b>	n/a	<b>Hertz</b>	60
<b>Housing Material</b>	NA	<b>HP</b>	1/10
<b>Motor Enclosure</b>	n/a	<b>Motor Insulation</b>	B
<b>Motor Phase</b>	1	<b>Motor Type</b>	BrushlessDC
<b>Nominal Efficiency</b>	85	<b>Return Eligibility</b>	Non-returnable, customized, or special-order item
<b>RPM</b>	1800	<b>Service Factor</b>	1
<b>Shipping Type</b>	Parcel	<b>Thermal Protection</b>	AutoOverload
<b>Voltage</b>	115 208 230 277		

### Dimensions

<b>Height</b>	5 in	<b>Length</b>	9 in
<b>Weight</b>	6.13 lbs	<b>Width</b>	5 in

### California Residents

**⚠ WARNING**

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit [www.P65Warnings.ca.gov](http://www.P65Warnings.ca.gov)