




SKU
319357

Job Name:
Mark:
Submitted By:
Date: 04/05/2026

Vari-Green Motor - 1/6 HP, 115V, 208-230V, 277V, 1725RPM , Product # 319357

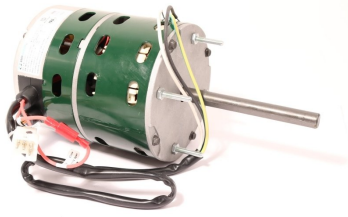

Performance Characteristics

| Power | Speed | Voltage | Frequency | Phase | Full Load Amp Draw |
|----------|-------|---------|-----------|-------|--------------------|
| 0.167 HP | 1800 | 277 | 60 | 1 | 1.1 |
| 0.167 HP | 1800 | 240 | 50 | 1 | 1.3 |
| 0.167 HP | 1800 | 115 | 50 | 1 | 2.2 |
| 0.167 HP | 1800 | 115 | 60 | 1 | 2.2 |
| 0.167 HP | 1800 | 230 | 50 | 1 | 1.3 |
| 0.167 HP | 1800 | 110 | 50 | 1 | 2.2 |
| 0.167 HP | 1800 | 208 | 60 | 1 | 1.3 |
| 0.167 HP | 1800 | 220 | 50 | 1 | 1.3 |
| 0.167 HP | 1800 | 277 | 50 | 1 | 1.1 |
| 0.167 HP | 1800 | 230 | 60 | 1 | 1.3 |
| 0.167 HP | 1800 | 208 | 50 | 1 | 1.3 |

Specifications

| | | | |
|--------------------|--------------------------|-----------------------------|---|
| Base Type | Extended Thru-Bolt Mount | Country of Origin (Primary) | VN,CN |
| Explosion Proof | n/a | Frame Size | n/a |
| Frame Type | n/a | Hertz | 60 |
| Housing Material | NA | HP | 1/6 |
| Motor Enclosure | n/a | Motor Insulation | B |
| Motor Phase | 1 | Motor Type | BrushlessDC |
| Nominal Efficiency | 85 | Return Eligibility | Non-returnable, customized, or special-order item |
| RPM | 1800 | Service Factor | 1 |
| Shipping Type | Parcel | Thermal Protection | AutoOverload |
| Voltage | 115 208 230 277 | | |

Dimensions

| | | | |
|--------|-------|--------|-------|
| Height | 5 in | Length | 11 in |
| Weight | 7 lbs | Width | 5 in |

California Residents

⚠ WARNING

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit www.P65Warnings.ca.gov