




SKU
319357

Job Name:
Mark:
Submitted By:
Date: 06/14/2026

Vari-Green Motor - 1/6 HP, 115V, 208-230V, 277V, 1725RPM , Product # 319357

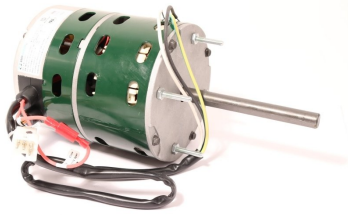

Performance Characteristics

Power	Speed	Voltage	Frequency	Phase	Full Load Amp Draw
0.167 HP	1800	110	50	1	2.2
0.167 HP	1800	115	50	1	2.2
0.167 HP	1800	230	60	1	1.3
0.167 HP	1800	115	60	1	2.2
0.167 HP	1800	208	60	1	1.3
0.167 HP	1800	208	50	1	1.3
0.167 HP	1800	230	50	1	1.3
0.167 HP	1800	277	60	1	1.1
0.167 HP	1800	240	50	1	1.3
0.167 HP	1800	277	50	1	1.1
0.167 HP	1800	220	50	1	1.3

Specifications

Base Type	Extended Thru-Bolt Mount	Country of Origin (Primary)	CN,VN
Explosion Proof	n/a	Frame Size	n/a
Frame Type	n/a	Hertz	60
Housing Material	NA	HP	1/6
Motor Enclosure	n/a	Motor Insulation	B
Motor Phase	1	Motor Type	BrushlessDC
Nominal Efficiency	85	Return Eligibility	Non-returnable, customized, or special-order item
RPM	1800	Service Factor	1
Shipping Type	Parcel	Thermal Protection	AutoOverload
Voltage	115 208 230 277		

Dimensions

Height	5 in	Length	11 in
Weight	7 lbs	Width	5 in

California Residents

⚠ WARNING

This product can expose you to chemicals including cadmium used in the processing of corrosion resistant metal and fasteners, which is known to the State of California to cause cancer and birth defects or other reproductive harm. For more information visit www.P65Warnings.ca.gov